


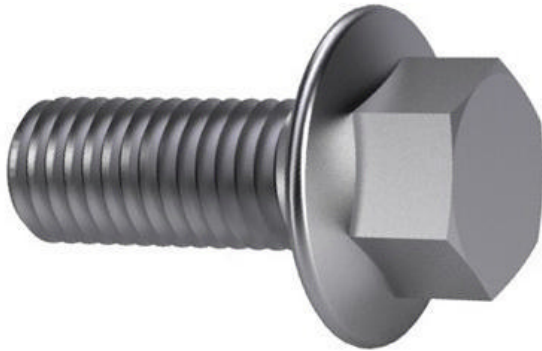

Hexagon flange bolt EN 1665 Steel Zinc plated 10.9 M16X60

Article number	04140.160.060
Brand	-
UBB	500650802720
UNSPSC	31162400
EAN	8717077294721
PKG. of 50	Full Box Only

Technical Parameters

Diameter	M16
Length	60 mm
Class	10.9
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info
Warning:
electroplating of
these products may
cause hydrogen
embrittlement.

Standards

EN	1665
ASME	≈B18.2.3.4M
ISO	≈4162
DIN	≈6921

Technical Specification

b (min.)	38
d-D	M16
dc (max.)	35
k (max.)	15.4
L (mm)	60
P	2
s	24

Technical Drawing

