


Hexagon socket head cap screw DIN 912 Steel Zinc plated 8.8 M3X20

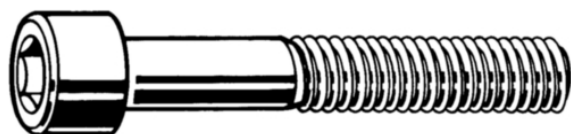

Article No.	07160.030.020
Brand	-
UBB	950351441122
UNSPSC	31161605
EAN	8715492070814
PKG. of 200	Full Box Only

Technical Parameters

Diameter (d-D)	M3
Length (L) (mm)	20
Class	8.8
Driving features	Hexagon socket
Head shape	Cylindrical head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Standards

NEN	1241
ASME	B18.3.1M
NF	E25-125
DIN	912
ISO	4762
BS	4168-1

Technical Specification

b	18
d_k (max.)	5.5
Full thread if $L \leq$	20
k (max.)	3
P	0.50
s	2.5

Technical Drawing

