



Hexagon socket set screw with dog point DIN 915 Steel Plain 45H M8X55

Article number	07820.080.055
Brand	-
UBB	500645132324
UNSPSC	31161518
EAN	8717077063112
PKG. of 100	Full Box Only

Technical Parameters

Diameter	M8
Length	55 mm
Class	45H
Driving features	Hexagon socket
Material	Steel
Thread direction	Right
Point	Dog
Surface treatment	Plain
Thread	Metric thread

Info

These set screws are designed for pressure loads and are not suitable for tensile- or shear loads.


Standards

NEN	2344
ASME	B18.3.6M
DIN	915
BS	4168-4
ISO	4028
NF	E27-182

Technical Specification

d-D	M8
dp (max.)	5.5
L (mm)	55
P	1.25
s	4
t (min.)	3
z long (min.)	4
z long if L ≥	12

Technical Drawing

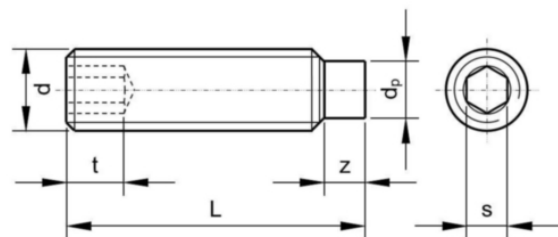

z short (min.)

2

FABORY