



## Hexagon socket set screw with dog point DIN 915 Steel Plain 45H M20X50

|                |               |
|----------------|---------------|
| Article number | 07820.200.050 |
| Brand          | -             |
| UBB            | 951351213339  |
| UNSPSC         | 31161518      |
| EAN            | 8715492162014 |
| PKG. of 10     | Full Box Only |

### Technical Parameters

|                   |                |
|-------------------|----------------|
| Diameter          | M20            |
| Length            | 50 mm          |
| Class             | 45H            |
| Driving features  | Hexagon socket |
| Material          | Steel          |
| Thread direction  | Right          |
| Point             | Dog            |
| Surface treatment | Plain          |
| Thread            | Metric thread  |

#### Info

These set screws are designed for pressure loads and are not suitable for tensile- or shear loads.


### Standards

|      |          |
|------|----------|
| NEN  | 2344     |
| NF   | E27-182  |
| BS   | 4168-4   |
| ISO  | 4028     |
| DIN  | 915      |
| ASME | B18.3.6M |

### Technical Specification

|               |     |
|---------------|-----|
| d-D           | M20 |
| dp (max.)     | 15  |
| L (mm)        | 50  |
| P             | 2.5 |
| s             | 10  |
| t (min.)      | 8   |
| z long (min.) | 10  |
| z long if L ≥ | 30  |

### Technical Drawing

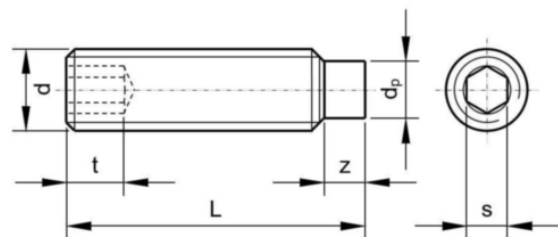

z short (min.)

5

**FABORY**