



Hexagon socket set screw with dog point DIN 915 Steel Plain 45H M20X90

Article number	07820.200.090
Brand	-
UBB	953351918883
UNSPSC	31161518
EAN	8715492162045
PKG. of 25	Full Box Only

Technical Parameters

Diameter	M20
Length	90 mm
Class	45H
Driving features	Hexagon socket
Material	Steel
Thread direction	Right
Point	Dog
Surface treatment	Plain
Thread	Metric thread

Info

These set screws are designed for pressure loads and are not suitable for tensile- or shear loads.


Standards

ISO	4028
BS	4168-4
NF	E27-182
NEN	2344
ASME	B18.3.6M
DIN	915

Technical Specification

d-D	M20
dp (max.)	15
L (mm)	90
P	2.5
s	10
t (min.)	8
z long (min.)	10
z long if L ≥	30

Technical Drawing

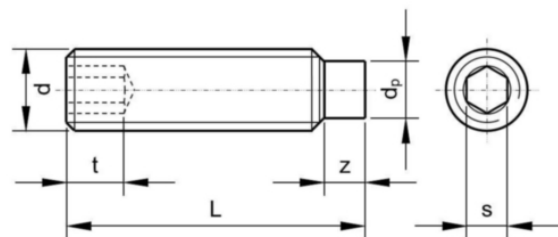

z short (min.)

5

FABORY