


Hexagon head bolt with hexagon nut DIN 601/555 Steel Plain 4.6 M12X55

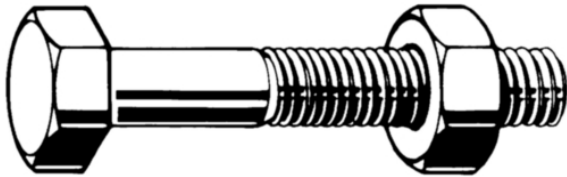

Article number	08000.120.055
Brand	-
UBB	500648012648
UNSPSC	31161620
EAN	8717077272743
PKG. of 100	Full Box Only

Technical Parameters

Diameter	M12
Length	55 mm
Class	4.6
Driving features	Hexagon
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Info	The property class of the corresponding nuts is 4 as a minimum.

Standards

DIN	601/555
NF	E25-115-1/E25-402
NEN	102/697
ISO	≈4016/4033

Technical Specification

b (min.): 125mmL≤200mm	36
b (min.): L200mm	49
b (min.): L≤125mm	30
d-D	M12
k	7.5
L (mm)	55
m	10
P	1.75
s	19

Technical Drawing

