


Cup head nib bolt with  
hexagon nut DIN 607/555  
Steel Plain 4.6 M10X40

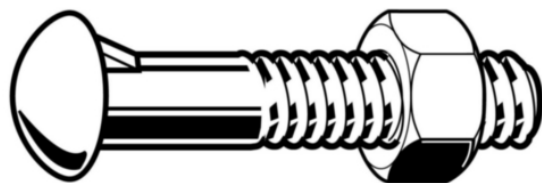

|                |               |
|----------------|---------------|
| Article number | 08007.100.040 |
| Brand          | -             |
| UBB            | 500650905374  |
| UNSPSC         | 31162400      |
| EAN            | 8717077305007 |
| PKG. of 100    | Full Box Only |

Technical Parameters

|                   |                                                                   |
|-------------------|-------------------------------------------------------------------|
| Diameter          | M10                                                               |
| Length            | 40 mm                                                             |
| Class             | 4.6                                                               |
| Head shape        | Cup head                                                          |
| Material          | Steel                                                             |
| Thread direction  | Right                                                             |
| Surface treatment | Plain                                                             |
| Thread            | Metric thread                                                     |
| Info              | The property class of the corresponding nuts is  4  as a minimum. |

Standards

|     |         |
|-----|---------|
| DIN | 607/555 |
|-----|---------|

Technical Specification

|                                 |       |
|---------------------------------|-------|
| b (min.): $L \leq 125\text{mm}$ | 26    |
| d-D                             | M10   |
| dk (max.)                       | 19.65 |
| g (max.)                        | 3.2   |
| k (max.)                        | 7.45  |
| L (mm)                          | 40    |
| m (js15)                        | 8     |
| P                               | 1.5   |
| s                               | 17    |

Technical Drawing

