


Flat countersunk nib bolt with hexagon nut DIN 604/555 Steel Plain 4.6 M6X25

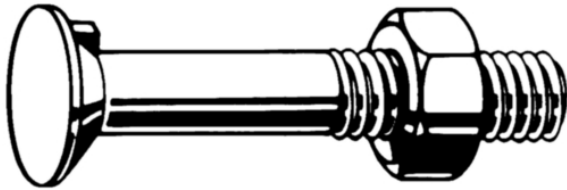

Article number	08070.060.025
Brand	-
UBB	500645150623
UNSPSC	31161612
EAN	8717077055971
PKG. of 500	Full Box Only

Technical Parameters

Diameter	M6
Length	25 mm
Class	4.6
Head shape	Countersunk head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Info	The property class of the corresponding nuts is 4 as a minimum.


Standards

DIN	604/555
-----	---------

Technical Specification

b (min.): 125mmL≤200mm	24
b (min.): L≤125mm	18
d-D	M6
dk (max.)	12.55
g (max.)	2.5
k	4
L (mm)	25
m	5
P	1

Technical Drawing

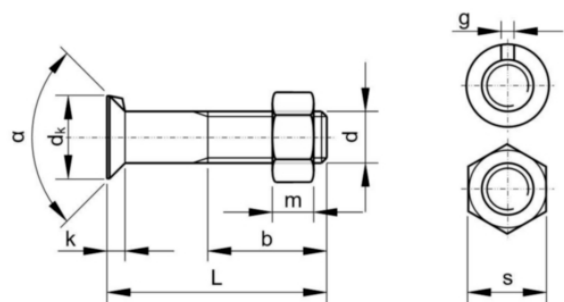

s 10

α (min.) 90