


Flat countersunk nib bolt with hexagon nut DIN 604/555 Steel Plain 4.6 M20X40

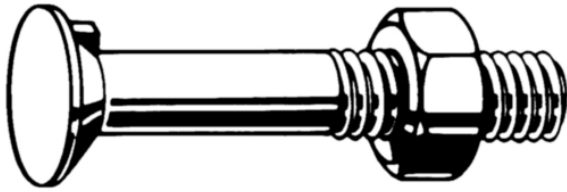

Article number	08070.200.040
Brand	-
UBB	500644845413
UNSPSC	31161612
EAN	8717077033092
PKG. of 25	Full Box Only

Technical Parameters

Diameter	M20
Length	40 mm
Class	4.6
Head shape	Countersunk head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Info	The property class of the corresponding nuts is 4 as a minimum.


Standards

DIN	604/555
-----	---------

Technical Specification

b (min.): 125mmL≤200mm	52
b (min.): L200mm	65
b (min.): L≤125mm	46
d-D	M20
dk (max.)	32.8
g (max.)	5.4
k	11.5
L (mm)	40
m	16

Technical Drawing

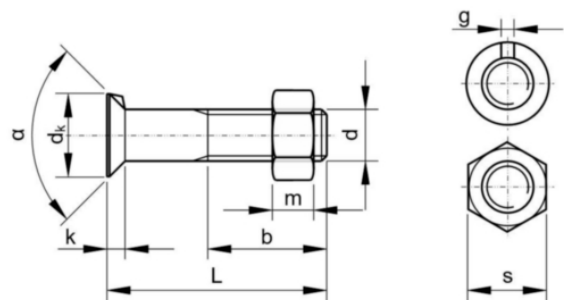

P 2.5

s 30

α (min.) 60