


Flat countersunk nib bolt with hexagon nut DIN 604/555 Steel Plain 4.6 M20X55

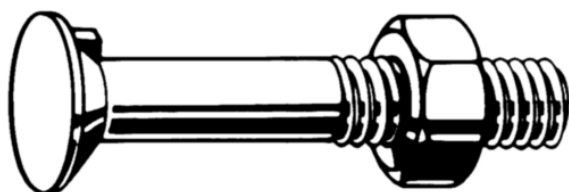

Article number	08070.200.055
Brand	-
UBB	500644845660
UNSPSC	31161612
EAN	8717077033115
PKG. of 25	Full Box Only

Technical Parameters

Diameter (d-D)	M20
Length (L) (mm)	55
Info	The property class of the corresponding nuts is 4 as a minimum.
Class	4.6
Head shape	Countersunk head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread


Standards

DIN	604/555
-----	---------

Technical Specification

b (min.): 125mm<L≤200mm	52
b (min.): L>200mm	65
b (min.): L≤125mm	46
d _k (max.)	32.8
g (max.)	5.4
k	11.5
m	16
P	2.50
s	30

Technical Drawing

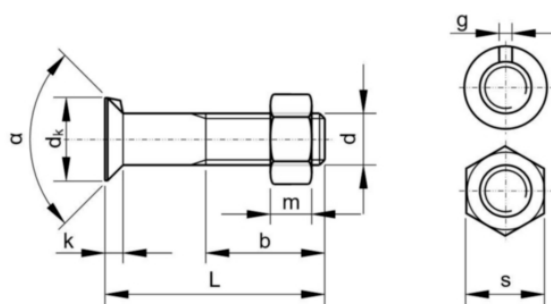

α (min.)

60°

FABORY
OF COURSE.
SETTING THE STANDARD
IN FASTENING SOLUTIONS