

Hexagon head bolt with hexagon nut DIN 601/555 Steel Zinc plated 4.8 M14X180

Article number	08200.140.180
Brand	-
UBB	952351341948
UNSPSC	31161620
EAN	8715493800632
PKG. of 25	Full Box Only

Technical Parameters

Diameter	M14
Length	180 mm
Class	4.6
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info
The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

ISO	≈4016/4033
DIN	601/555
NEN	102/697
NF	E25-115-1/E25-402

Technical Specification

b (min.): 125mmL≤200mm	40
b (min.): L200mm	53
b (min.): L≤125mm	34
d-D	M14
k	8.8

Technical Drawing

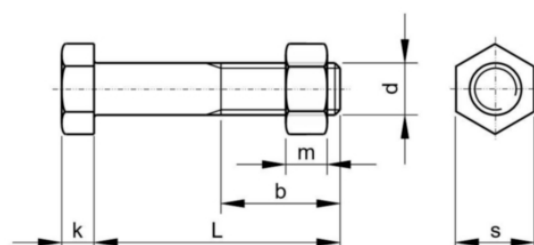

L (mm)	180
m	11
P	2
s	22