

Flat countersunk square neck bolt with long square with hexagon nut DIN 605/555 Steel Zinc plated 4.6 M8X30

Article number	08206.080.030
Brand	-
UBB	951351343284
UNSPSC	31161612
EAN	8715492553393
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M8
Length	30 mm
Class	4.6
Head shape	Countersunk head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Info	The property class of the corresponding nuts is 4 as a minimum.


Standards

DIN	605/555
-----	---------

Technical Specification

b (min.)	22
d-D	M8
dk (max.)	20.65
L (mm)	30
m	6.5
P	1.25
fn (max.)	9.45
s	13

Technical Drawing

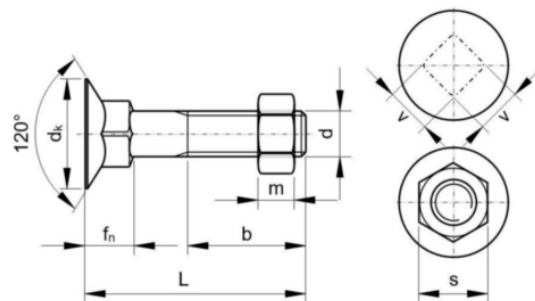

v (max.)	8.58
----------	------

FABORY