

Carriage bolt with hexagon nut DIN 603/555 Steel Zinc plated 4.8 M5X50

Article number	08250.050.050
Brand	-
UBB	950351600271
UNSPSC	31161612
EAN	8715492554789
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M5
Length	50 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Info	The property class of the corresponding nuts is 4 as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

NEN	≈303/697
ISO	≈8677/4034
BS	≈4933/3692
NF	≈E27-351/E25-402
DIN	603/555

Technical Specification

b (min.): 125mmL≤200mm	22
b (min.): L≤125mm	16
d-D	M5
dk (max.)	13.55
k (max.)	3.3
L (mm)	50
m	4
P	0.8
fn (max.)	4.1

Technical Drawing

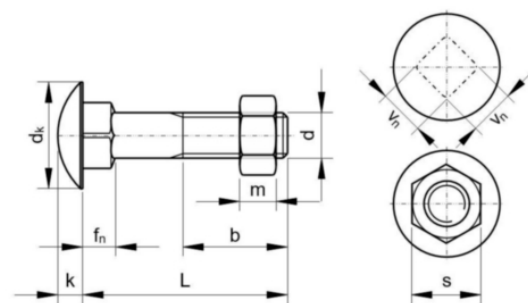

s

8

Vn (max.)

5.48

