

Carriage bolt with hexagon nut DIN 603/555 Steel Zinc plated 4.8 M5X55

Article number	08250.050.055
Brand	-
UBB	500645157735
UNSPSC	31161612
EAN	8717077066403
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M5
Length	55 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info
The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

ISO	≈8677/4034
DIN	603/555
BS	≈4933/3692
NF	≈E27-351/E25-402
NEN	≈303/697

Technical Specification

b (min.): 125mmL≤200mm	22
b (min.): L≤125mm	16
d-D	M5
dk (max.)	13.55
k (max.)	3.3
L (mm)	55
m	4
P	0.8
fn (max.)	4.1

Technical Drawing

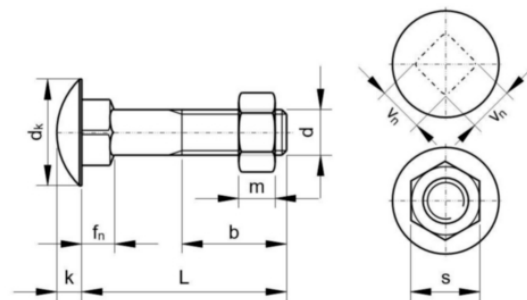

s

8

Vn (max.)

5.48

