


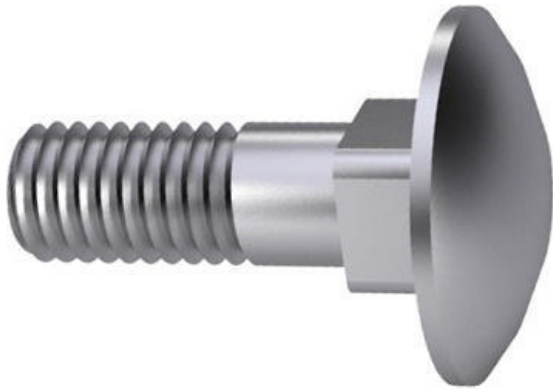

## Carriage bolt DIN 603 Steel Plain 8.8 M6X16

|                |               |
|----------------|---------------|
| Article number | 08310.060.016 |
| Brand          | -             |
| UBB            | 950351616863  |
| UNSPSC         | 31161612      |
| EAN            | 8715492558213 |
| PKG. of 200    | Full Box Only |

### Technical Parameters

|                    |               |
|--------------------|---------------|
| Diameter           | M6            |
| Length             | 16 mm         |
| Threaded pitch (P) | 1             |
| Class              | 8.8           |
| Material           | Steel         |
| Thread direction   | Right         |
| Surface treatment  | Plain         |
| Thread             | Metric thread |

### Standards

|     |       |
|-----|-------|
| ISO | ≈8677 |
| NEN | ≈303  |
| DIN | 603   |
| BS  | ≈4933 |

### Technical Specification

|                           |       |
|---------------------------|-------|
| b (min.):<br>125mmL≤200mm | 24    |
| b (min.): L≤125mm         | 18    |
| d-D                       | M6    |
| dk (max.)                 | 16.55 |
| k (max.)                  | 3.88  |
| L (mm)                    | 16    |
| P                         | 1     |
| fn (max.)                 | 4.6   |
| Vn (max.)                 | 6.48  |

### Technical Drawing

