


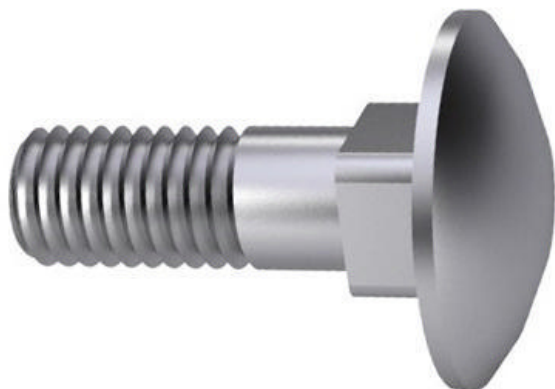

Carriage bolt DIN 603 Steel Plain 8.8 M8X20

Article number	08310.080.020
Brand	-
UBB	950351617770
UNSPSC	31161612
EAN	8715492558305
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M8
Length	20 mm
Threaded pitch (P)	1.25
Class	8.8
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread

Standards

NEN	≈303
ISO	≈8677
DIN	603
BS	≈4933

Technical Specification

b (min.): 125mmL≤200mm	28
b (min.): L200mm	41
b (min.): L≤125mm	22
d-D	M8
dk (max.)	20.65
k (max.)	4.88
L (mm)	20
P	1.25
fn (max.)	5.6
Vn (max.)	8.58

Technical Drawing

