


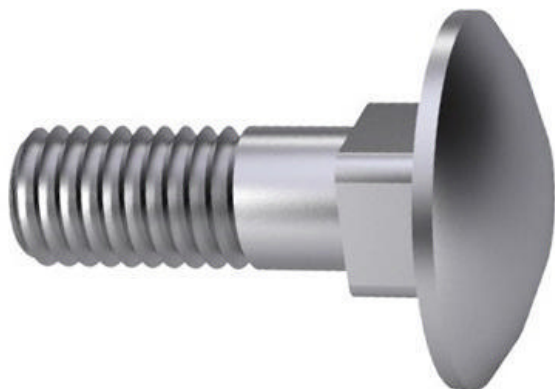

Carriage bolt DIN 603 Steel
Plain 8.8 M8X60

Article number	08310.080.060
Brand	-
UBB	950351618505
UNSPSC	31161612
EAN	8715492558381
PKG. of 100	Full Box Only

Technical Parameters

Diameter	M8
Length	60 mm
Threaded pitch (P)	1.25
Class	8.8
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread

Standards

NEN	≈303
BS	≈4933
ISO	≈8677
DIN	603

Technical Specification

b (min.): 125mmL≤200mm	28
b (min.): L200mm	41
b (min.): L≤125mm	22
d-D	M8
dk (max.)	20.65
k (max.)	4.88
L (mm)	60
P	1.25
fn (max.)	5.6
Vn (max.)	8.58

Technical Drawing

