


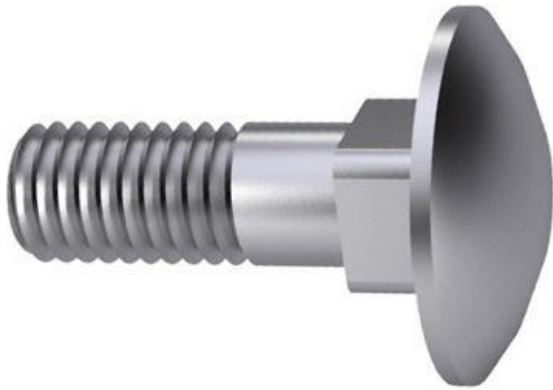

Carriage bolt DIN 603 Steel Plain 8.8 M8X70

Article number	08310.080.070
Brand	-
UBB	950351618687
UNSPSC	31161612
EAN	8715492558404
PKG. of 100	Full Box Only

Technical Parameters

Diameter	M8
Length	70 mm
Threaded pitch (P)	1.25
Class	8.8
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread

Standards

BS	≈4933
DIN	603
ISO	≈8677
NEN	≈303

Technical Specification

b (min.): 125mmL≤200mm	28
b (min.): L200mm	41
b (min.): L≤125mm	22
d-D	M8
dk (max.)	20.65
k (max.)	4.88
L (mm)	70
P	1.25
fn (max.)	5.6
Vn (max.)	8.58

Technical Drawing

