


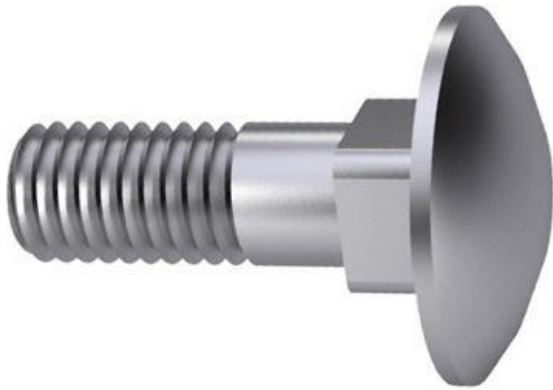

Carriage bolt DIN 603 Steel Plain 8.8 M10X60

Article number	08310.100.060
Brand	-
UBB	950351619834
UNSPSC	31161612
EAN	8715492558527
PKG. of 100	Full Box Only

Technical Parameters

Diameter	M10
Length	60 mm
Threaded pitch (P)	1.5
Class	8.8
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread

Standards

DIN	603
NEN	≈303
ISO	≈8677
BS	≈4933

Technical Specification

b (min.): 125mmL≤200mm	32
b (min.): L200mm	45
b (min.): L≤125mm	26
d-D	M10
dk (max.)	24.65
k (max.)	5.38
L (mm)	60
P	1.5
fn (max.)	6.6
Vn (max.)	10.58

Technical Drawing

