


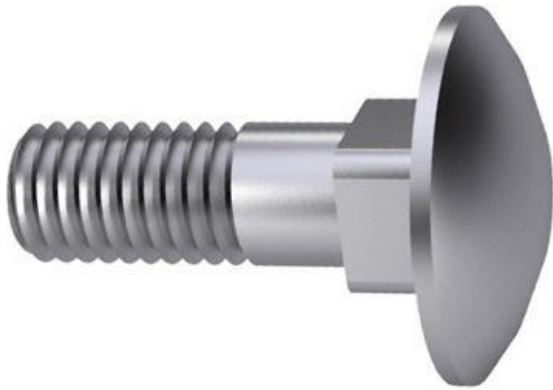

Carriage bolt DIN 603 Steel Zinc plated 8.8 M8X20

Article number	08320.080.020
Brand	-
UBB	951351994466
UNSPSC	31161612
EAN	8715492558824
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M8
Length	20 mm
Threaded pitch (P)	1.25
Class	8.8
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Standards

DIN	603
ISO	≈8677
NEN	≈303
BS	≈4933

Technical Specification

b (min.): 125mmL≤200mm	28
b (min.): L200mm	41
b (min.): L≤125mm	22
d-D	M8
dk (max.)	20.65
k (max.)	4.88
L (mm)	20
P	1.25
fn (max.)	5.6
Vn (max.)	8.58

Technical Drawing

