


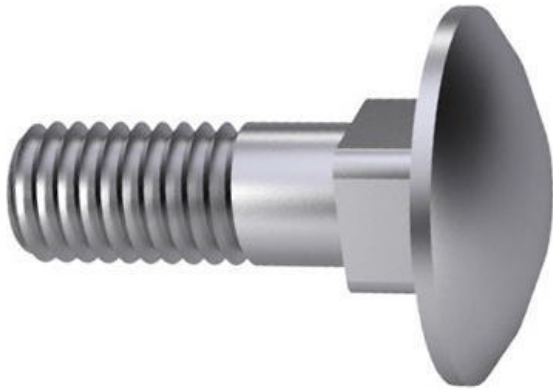

Carriage bolt DIN 603 Steel Zinc plated 8.8 M12X35

Article number	08320.120.035
Brand	-
UBB	954351310246
UNSPSC	31161612
EAN	8715492559043
PKG. of 100	Full Box Only

Technical Parameters

Diameter	M12
Length	35 mm
Threaded pitch (P)	1.75
Class	8.8
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Standards

DIN	603
ISO	≈8677
NEN	≈303
BS	≈4933

Technical Specification

b (min.): 125mmL≤200mm	36
b (min.): L200mm	49
b (min.): L≤125mm	30
d-D	M12
dk (max.)	30.65
k (max.)	6.95
L (mm)	35
P	1.75
fn (max.)	8.75
Vn (max.)	12.7

Technical Drawing

