


## Spacer, 2 x internal thread Free-cutting steel Zinc plated M2,5X25X7

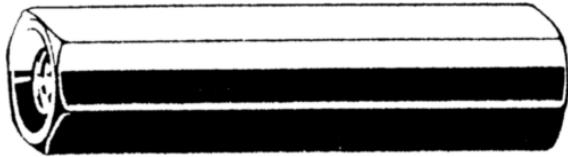

Article number	11396.025.025
Brand	-
UBB	950355728250
UNSPSC	31161816
EAN	8715492571793
PKG. of 100	Full Box Only

### Technical Parameters

Diameter	M2.5
Length	25 mm
Material	Free-cutting steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Type no.	H1200
Info	When L = L# the spacer has a continuous thread. Depending on manufacturer and availability parts with slightly different dimensions but with equal functionality may be supplied

### Standards

### Technical Specification

d-D	M2.5
L (mm)	25
L1	7
P	0.45
s	5

### Technical Drawing

