


## Spacer, internal and external thread Free-cutting steel Zinc plated M2,5X20X7

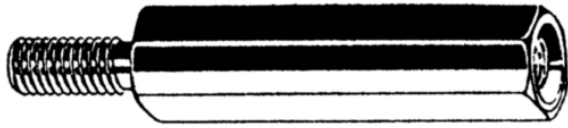

Article number	11398.025.020
Brand	-
UBB	950355729407
UNSPSC	31161816
EAN	8715492572127
PKG. of 100	Full Box Only

### Technical Parameters

Diameter	M2.5
Length	20 mm
Material	Free-cutting steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Type no.	H1202
Info	Depending on manufacturer and availability parts with slightly different dimensions but with equal functionality may be supplied

### Standards

### Technical Specification

d-D	M2.5
L (mm)	20
L1	5.6
L2	7
P	0.45
s	4

### Technical Drawing

