


## Spacer, internal and external thread Free-cutting steel Zinc plated M3X5X2,5

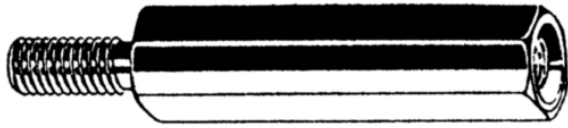

Article number	11398.030.005
Brand	-
UBB	950355643012
UNSPSC	31161816
EAN	8715492572141
PKG. of 100	Full Box Only

### Technical Parameters

Diameter	M3
Length	5 mm
Material	Free-cutting steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Type no.	H1202
Info	Depending on manufacturer and availability parts with slightly different dimensions but with equal functionality may be supplied

### Standards

### Technical Specification

d-D	M3
L (mm)	5
L1	6
L2	2.5
P	0.5
s	5.5

### Technical Drawing

