


Spacer, internal and external thread Free-cutting steel Zinc plated M3X13.5X7

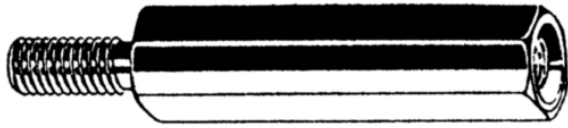

Article number	11398.030.013
Brand	-
UBB	950355729811
UNSPSC	31161816
EAN	8715492572189
PKG. of 100	Full Box Only

Technical Parameters

Diameter	M3
Length	13 mm
Material	Free-cutting steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Type no.	H1202
Info	Depending on manufacturer and availability parts with slightly different dimensions but with equal functionality may be supplied

Standards

Technical Specification

d-D	M3
L (mm)	13
L1	6
L2	7
P	0.5
s	5.5

Technical Drawing

