


## Spacer, internal and external thread Free-cutting steel Zinc plated M4X8X5

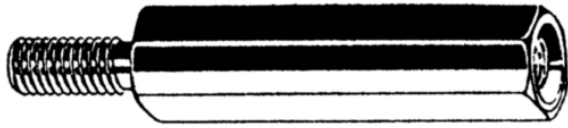

Article number	11398.040.008
Brand	-
UBB	500645165571
UNSPSC	31161816
EAN	8717077067189
PKG. of 100	Full Box Only

### Technical Parameters

Diameter	M4
Length	8 mm
Material	Free-cutting steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Type no.	H1202
Info	Depending on manufacturer and availability parts with slightly different dimensions but with equal functionality may be supplied

### Standards

### Technical Specification

d-D	M4
L (mm)	8
L1	8
L2	5
P	0.7
s	7

### Technical Drawing

