


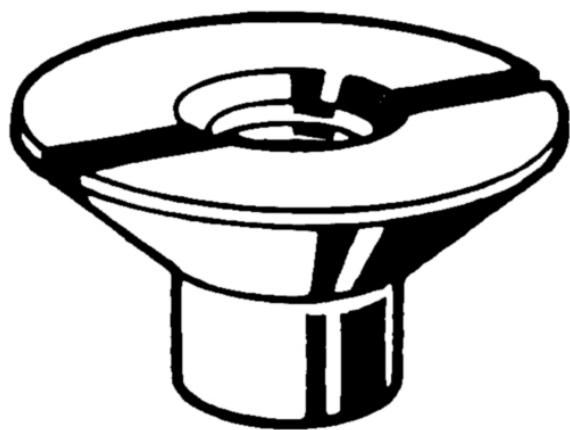

Slotted countersunk nut
Free-cutting steel Zinc
plated M10

Article number	11560.100.024
Brand	-
UBB	950355094703
UNSPSC	31161727
EAN	8715492573193
PKG. of 250	Full Box Only

Technical Parameters

Diameter	M10
Driving features	Slotted
Material	Free-cutting steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Standards

Technical Specification

d-D	M10
d1	12
d2	24
m	12
n	2.5
P	1.5
T	2

Technical Drawing

