



Slotted round nut for hook spanners MF DIN 1804 W Steel Plain |5| M24X1,50

Article number	11572.240.150
Brand	-
UBB	950355725447
UNSPSC	31161727
EAN	8715492573285
PKG. of 5	Full Box Only

Technical Parameters

Diameter	M24
Class	5
Driving features	Slotted
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric fine thread

Info

Slotted round nuts for hookspanners when combined with internal tab washers according to DIN 462 provide mechanical locking. They are easily assembled with a hook wrench (hook spanner) e.g. to DIN 1810.


Standards

DIN	1804-W
-----	--------

Technical Specification

b	6
d-D	M24
d2 (h11)	42
h (h14)	9
Number of slots	4

Technical Drawing

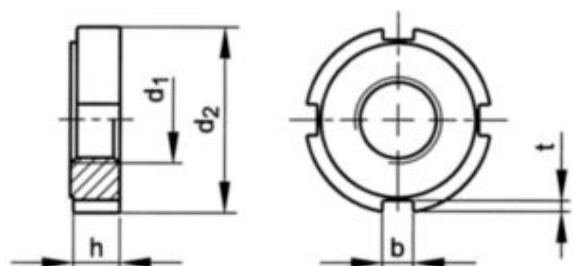

P 1.5

t 2.5

