



Hexagon slotted and castle nut MF DIN 935-1 Steel Plain 6 M10X1,25

Article number	12022.100.125
Brand	-
UBB	500648182359
UNSPSC	31161707
EAN	8717077215702
PKG. of 100	Full Box Only

Technical Parameters

Diameter	M10
Class	6
Driving features	Hexagon
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric fine thread

Info * These dimensions are supplied with the 'old' widths across flats sizes according to DIN. Guide values for advised split pins (cotter pins) acc. to DIN 94 (ISO 1234). Depending on availability the dimensions may deviate.


Standards

DIN	935-1
NEN	729

Technical Specification

d-D	M10
m	12
n	2.8
Number of slots	6
P	1.25

Technical Drawing

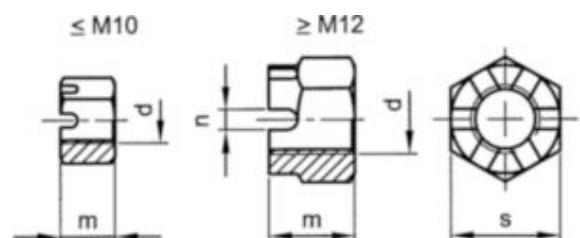

s

17

Split pin DIN 94

2.5