


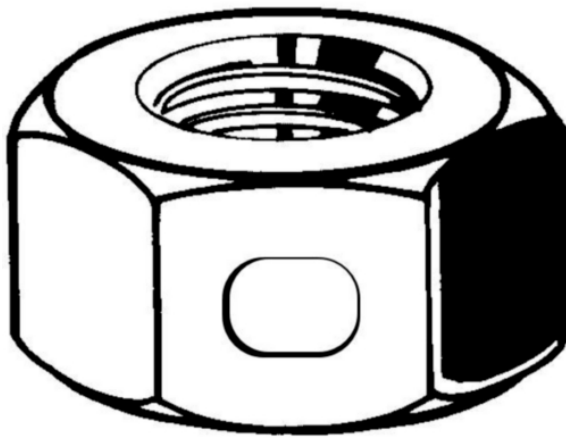

BILOC Prevailing torque type hexagon nut, all metal DIN ≈980V Steel Zinc plated 8 M12

Article number	12385.120.001
Brand	-
UBB	500650968729
UNSPSC	31162400
EAN	8717077311404
PKG. of 500	Full Box Only

Technical Parameters

Diameter	M12
Class	8
Driving features	Hexagon
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Standards

ISO	≈7042
DIN	≈980-V

Technical Specification

d-D	M12
m (max.)	10.8
P	1.75
s	19

Technical Drawing

