


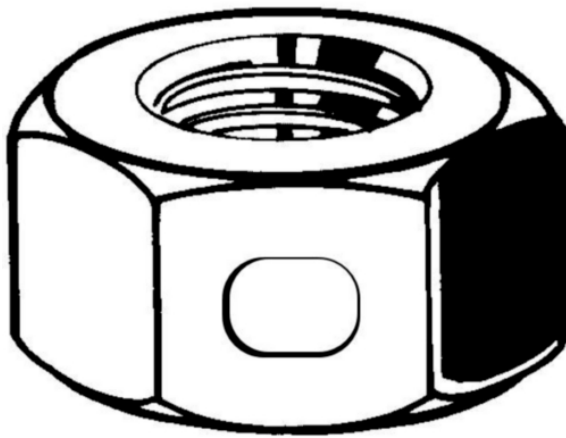

BILOC Prevailing torque type hexagon nut, all metal DIN ≈980V Steel Zinc plated 10 M8

Article number	12485.080.001
Brand	-
UBB	500650971772
UNSPSC	31162400
EAN	8717077311701
PKG. of 1000	Full Box Only

Technical Parameters

Diameter	M8
Class	10
Driving features	Hexagon
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Standards

DIN	≈980-V
ISO	≈7042

Technical Specification

d-D	M8
m (max.)	6.8
P	1.25
s	13

Technical Drawing

