


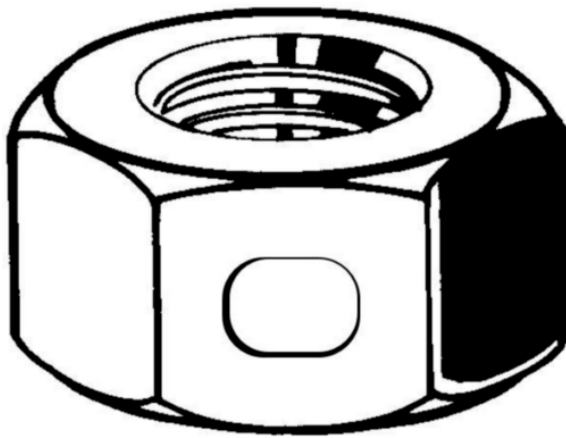

BILOC Prevailing torque type hexagon nut, all metal DIN ≈980V Steel Zinc plated 10 M20

Article number	12485.200.001
Brand	-
UBB	500650972192
UNSPSC	31162400
EAN	8717077311749
PKG. of 50	Full Box Only

Technical Parameters

Diameter	M20
Class	10
Driving features	Hexagon
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Standards

ISO	≈7042
DIN	≈980-V

Technical Specification

d-D	M20
m (max.)	18
P	2.5
s	30

Technical Drawing

