


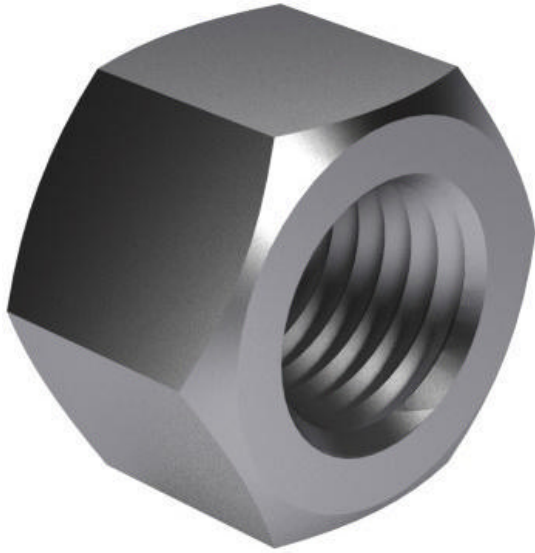

Prevailing torque type hexagon nut, all metal DIN 980V Steel Zinc plated 8 M20

Article number	12858.200.001
Brand	-
UBB	951355005939
UNSPSC	31161727
EAN	8715492580030
PKG. of 25	Full Box Only

Technical Parameters

Diameter	M20
Class	8
Driving features	Hexagon
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Standards

NEN	2452
DIN	980-V
BS	4929-1
ISO	7042
NF	E25-410

Technical Specification

d-D	M20
h (max.)	20
P	2.5
s	30

Technical Drawing

