


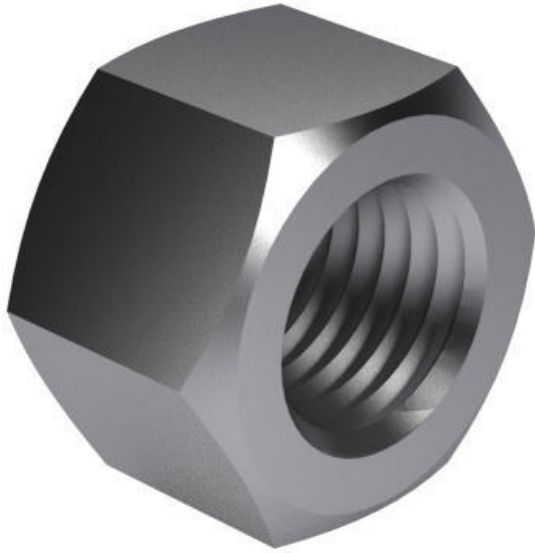

Prevailing torque type hexagon nut, all metal DIN 980V Steel Zinc plated 8 M24

Article number	12858.240.001
Brand	-
UBB	951355361597
UNSPSC	31161727
EAN	8715493508910
PKG. of 25	Full Box Only

Technical Parameters

Diameter	M24
Class	8
Driving features	Hexagon
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Standards

DIN	980-V
NF	E25-410
NEN	2452
BS	4929-1
ISO	7042

Technical Specification

d-D	M24
h (max.)	24
P	3
s	36

Technical Drawing

