


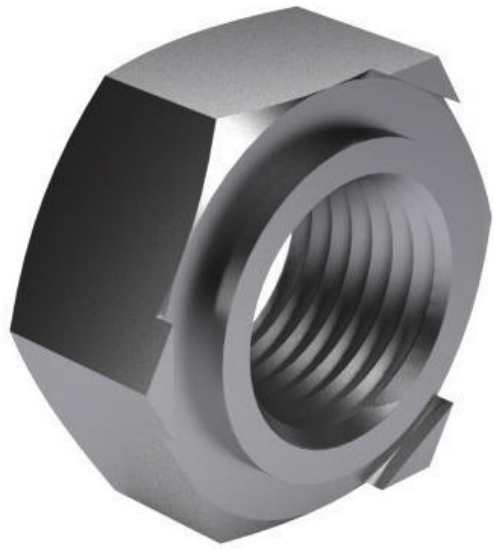

Hexagon weld nut DIN 929 Steel Max. 0,25%C Plain M10

Article number	14020.100.001
Brand	-
UBB	950355149267
UNSPSC	31161731
EAN	8715492581754
PKG. of 500	Full Box Only

Technical Parameters

Diameter	M10
Driving features	Hexagon
Material	Steel
Material technical	Max. 0.25%C
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Info	These weld nuts are intended for use with fasteners in property classes 8.8

Standards

DIN	929
-----	-----

Technical Specification

d-D	M10
Hole $\varnothing$ (H11)	12.5
m (h14)	8
P	1.5
s (h13)	17

Technical Drawing

