

Self-clinching blind stand off Steel Zinc plated M3X4,18X12X5

Article number	14421.030.012
Brand	-
UBB	500656714010
UNSPSC	31161816
EAN	8712423015647
PKG. of 1000	Full Box Only

Technical Parameters


Diameter	M3
Length	12 mm
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Info	Steel self-clinching blind stand offs are suitable for use in steel sheet with a maximum hardness of HRB70. For steel sheets with higher hardnesses, rivet bushes are recommended.

Standards

Technical Specification

B (min.)	5
C	4.18
d-D	M3
Hole size	4.2
L (mm)	12
Min. distance sheet edge	6

Technical Drawing

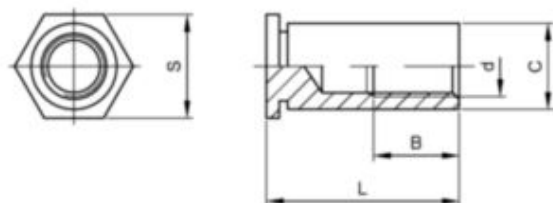

Min. recommended sheet thickness 1

S  4.8