


**Studbolt with 2 heavy hexagon nuts ASME B16.5/ B18.2.2 Steel ASTM A193 - ASTM A194 Plain Gr.B7 - Gr.2H 3/8X175 (6.7/8)**

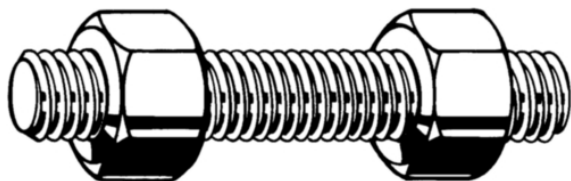

Article number	22080.096.175
Brand	-
UBB	500578014044
UNSPSC	31161619
EAN	8715494332477
PKG. of 1	Full Box Only

**Technical Parameters**

Diameter (inch)	3/8
Length (L) (mm)	175
Length (L) (Inch - ft)	6.7/8

**Info**  
Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

Class	Gr.B7 - Gr.2H
Material	Steel
Material technical	ASTM A193 - ASTM A194
Thread direction	Right
Surface treatment	Plain
Thread	Unified National Coarse

**Standards**

ASTM	A193/A194
BS	≈4882
ASME	B16.5/B18.2.2

**Technical Specification**

B	11/16
---	-------

**Technical Drawing**

M 9  
Threads per inch 16

**UP COURSE.**  
SETTING THE STANDARD  
IN FASTENING SOLUTIONS

