


Studbolt with 2 heavy hexagon nuts ASME B16.5/ B18.2.2 Steel ASTM A193 - ASTM A194 Zinc plated Gr.B7 - Gr.2H 3/4X75 (3)

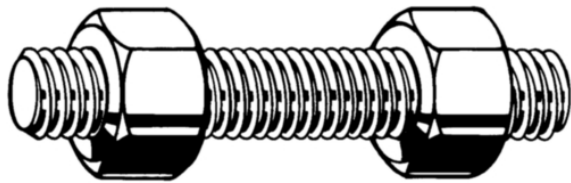

Article number	22082.191.076
Brand	-
UBB	500578457656
UNSPSC	31161619
EAN	8715494375702
PKG. of 1	Full Box Only

Technical Parameters

Diameter (inch)	3/4
Length (L) (mm)	75
Length (L) (Inch - ft)	3 Inch
Class	Gr.B7 - Gr.2H
Material	Steel
Surface treatment	Zinc plated
Thread direction	Right
Thread	Unified National Coarse
Material technical	ASTM A193 - ASTM A194

Info

Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

Standards

ASME	B16.5/B18.2.2
BS	≈4882
ASTM	A193/A194

Technical Specification

B	1.1/4
---	-------

Technical Drawing

M 18.7

Threads per inch 10

