


## Studbolt with 2 heavy hexagon nuts ASME B16.5/ B18.2.2 Steel ASTM A193 - ASTM A194 Plain Gr.B7M - Gr.2HM 1/2X85 (3.3/8)

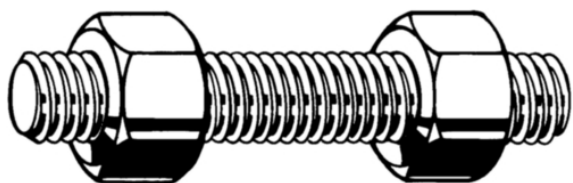

Article number	22085.127.085
Brand	-
UBB	500578757477
UNSPSC	31161619
EAN	8715494376679
PKG. of 1	Full Box Only

### Technical Parameters

Diameter (inch)	1/2
Length (L) (mm)	85
Length (L) (Inch - ft)	3.3/8

#### Info

Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

Class	Gr.B7M - Gr.2HM
Material	Steel
Material technical	ASTM A193 - ASTM A194
Thread direction	Right
Surface treatment	Plain
Thread	Unified National Coarse

### Standards

BS	≈4882
ASTM	A193/A194
ASME	B16.5/B18.2.2

### Technical Specification

B	7/8
---	-----

### Technical Drawing

M 12.3

Threads per inch 13

**UP COURSE.**

SETTING THE STANDARD  
IN FASTENING SOLUTIONS

