


Studbolt with 2 heavy hexagon nuts ASME B16.5/ B18.2.2 Steel ASTM A193 - ASTM A194 Plain Gr.B7M - Gr.2HM 1 Inch X310 (12.1/4)

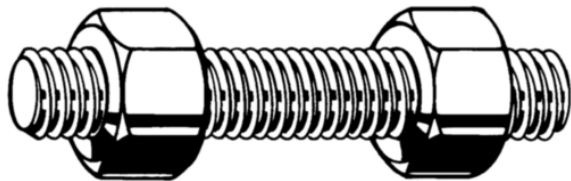

Article number	22085.254.311
Brand	-
UBB	500578787904
UNSPSC	31161619
EAN	8715494389662
PKG. of 1	Full Box Only

Technical Parameters

Diameter (inch)	1 Inch
Length (L) (mm)	310
Length (L) (Inch - ft)	12.1/4
Class	Gr.B7M - Gr.2HM
Material	Steel
Surface treatment	Plain
Thread direction	Right
Thread	Unified National Coarse
Material technical	ASTM A193 - ASTM A194

Info

Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

Standards

ASME	B16.5/B18.2.2
ASTM	A193/A194
BS	≈4882

Technical Specification

B	1.5/8
---	-------

Technical Drawing

M 25

Threads per inch 8

