


Studbolt with 2 heavy hexagon nuts ASME B16.5/ B18.2.2 Steel ASTM A320 - ASTM A194 Plain Gr.L7 - Gr.4 1.1/8X520 (20.1/2)

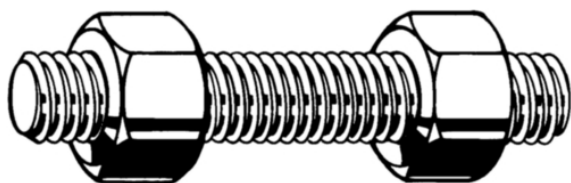

Article number	22330.285.520
Brand	-
UBB	500578922477
UNSPSC	31161619
EAN	8715494424998
PKG. of 1	Full Box Only

Technical Parameters

Diameter (inch)	1.1/8
Length (L) (mm)	520
Length (L) (Inch - ft)	20.1/2

Info

Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

Class	Gr.L7 - Gr.4
Material	Steel
Material technical	ASTM A320 - ASTM A194
Thread direction	Right
Surface treatment	Plain

Thread 8 Unified National

Info

Grade 4 nuts are no longer in ASTM A194/A194M and will be phased out gradually.

Standards

ASME	B16.5/B18.2.2
ASTM	A193/A194
BS	≈4882

It is advised to use Grade 7 nuts instead.

SETTING THE STANDARD
IN FASTENING SOLUTIONS

Technical Specification

B	1.13/16
M	28.2
Threads per inch	8

Technical Drawing

