


**Studbolt with 2 heavy
hexagon nuts ASME B16.5/
B18.2.2 Stainless steel ASTM
A193 - ASTM A194 Gr.B8
Cl.2 - Gr.8 1.1/8X155 (6.1/8)**

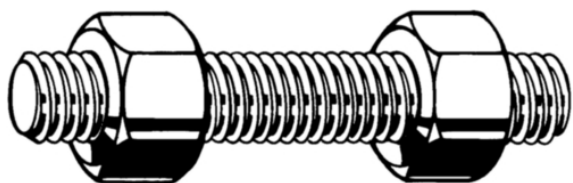

Article number	22530.285.155
Brand	-
UBB	500578526880
UNSPSC	31161619
EAN	8715494385114
PKG. of 1	Full Box Only

Technical Parameters

Diameter (inch)	1.1/8
Length (L) (mm)	155
Length (L) (Inch - ft)	6.1/8

Info
Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

Class	Gr.B8 Cl.2 - Gr.8
Material	Stainless steel
Material technical	ASTM A193 - ASTM A194
Thread direction	Right
Thread	8 Unified National

Standards

ASME	B16.5/B18.2.2
BS	≈4882
ASTM	A193/A194

Technical Specification

B	1.13/16
M	28.2
Threads per inch	8

Technical Drawing

FABORY *OF COURSE.*
SETTING THE STANDARD
IN FASTENING SOLUTIONS

