


Studbolt with 2 heavy hexagon nuts ASME B16.5/ B18.2.2 Stainless steel ASTM A193 - ASTM A194 Gr.B8 - Gr.8 7/8X270 (10.5/8)

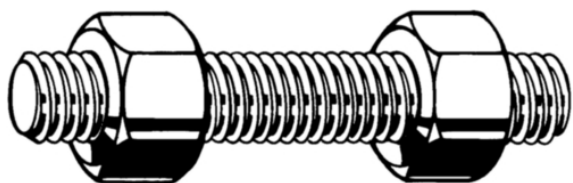

Article number	22534.222.270
Brand	-
UBB	500578993171
UNSPSC	31161619
EAN	8715494412216
PKG. of 1	Full Box Only

Technical Parameters

Diameter (inch)	7/8
Length (L) (mm)	270
Length (L) (Inch - ft)	10.5/8

Info

Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

Class	Gr.B8 - Gr.8
Material	Stainless steel
Material technical	ASTM A193 - ASTM A194
Thread direction	Right
Thread	Unified National Coarse

Standards

ASME	B16.5/B18.2.2
ASTM	A193/A194
BS	≈4882

Technical Specification

B	1.7/16
M	21.8

Technical Drawing

Threads per inch 9

FABORY OF COURSE.
SETTING THE STANDARD
IN FASTENING SOLUTIONS

