


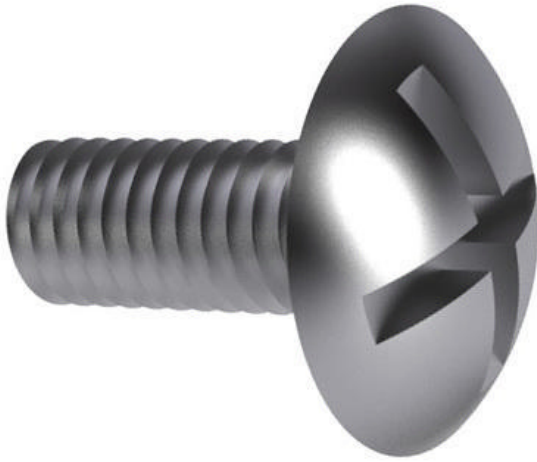

Double slotted mushroom head screw NF ≈E25-129 Steel Zinc plated 4.8 M10X40

Article number	24650.100.040
Brand	-
UBB	951353573094
UNSPSC	31161504
EAN	8715492638854
PKG. of 100	Full Box Only

Technical Parameters

Diameter	M10
Length	40 mm
Class	4.8
Driving features	Slotted
Head shape	Button head
Material	Steel
Surface treatment	Zinc plated
Thread	Metric thread

Standards

NF	≈E25-129
----	----------

Technical Specification

d-D	M10
dk (max.)	25
k (max.)	5.5
L (mm)	40
n	2.5
P	1.5

Technical Drawing

