


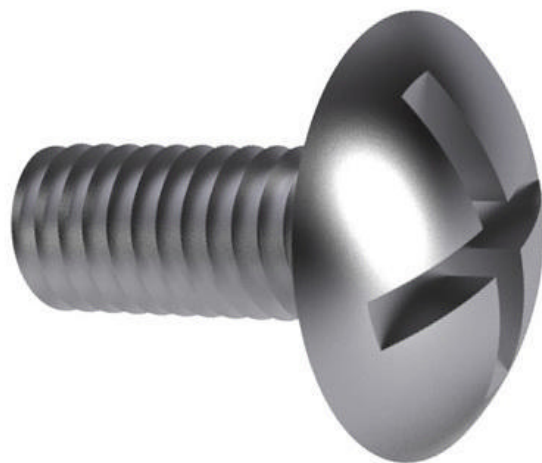

Double slotted mushroom head screw NF E25-129 Steel Zinc plated 4.8 M5X10

Article number	24862.050.010
Brand	-
UBB	950353761774
UNSPSC	31161504
EAN	8715493593664
PKG. of 500	Full Box Only

Technical Parameters

Diameter	M5
Length	10 mm
Class	4.8
Driving features	Slotted
Head shape	Button head
Material	Steel
Surface treatment	Zinc plated
Thread	Metric thread

Standards

NF	E25-129
----	---------

Technical Specification

d-D	M5
Thread length (min.)	38
dk (max.)	12.5
Full thread if $L \leq$	50
k (max.)	2.7
L (mm)	10
n	1.2
P	0.8
t (min.)	1.2

Technical Drawing

