


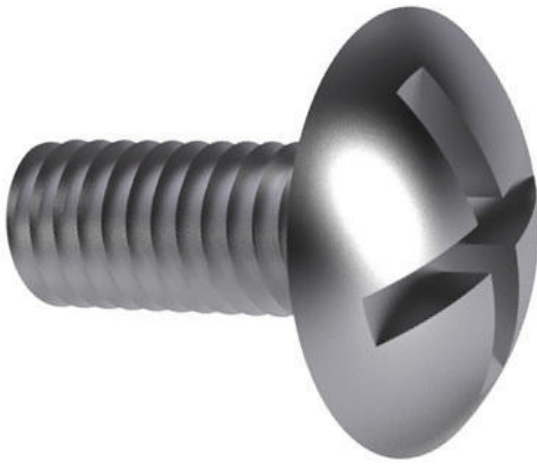

Double slotted mushroom head screw NF E25-129 Steel Zinc plated 4.8 M6X25

Article number	24862.060.025
Brand	-
UBB	950353763184
UNSPSC	31161504
EAN	8715493593855
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M6
Length	25 mm
Class	4.8
Driving features	Slotted
Head shape	Button head
Material	Steel
Surface treatment	Zinc plated
Thread	Metric thread

Standards

NF	E25-129
----	---------

Technical Specification

d-D	M6
Thread length (min.)	38
dk (max.)	15
Full thread if $L \leq$	60
k (max.)	3.3
L (mm)	25
n	1.6
P	1
t (min.)	1.5

Technical Drawing

