


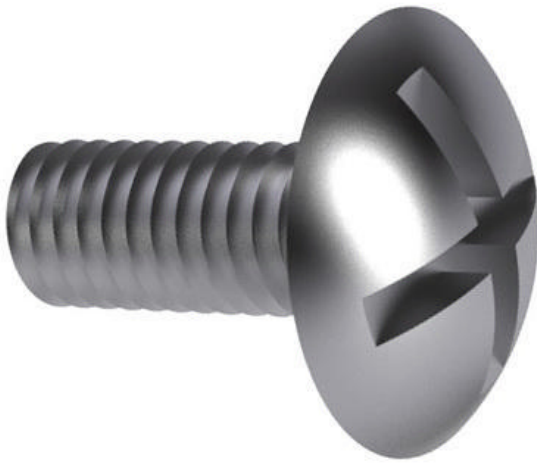

Double slotted mushroom head screw NF E25-129 Steel Zinc plated 4.8 M8X50

Article number	24862.080.050
Brand	-
UBB	950353758986
UNSPSC	31161504
EAN	8715493594043
PKG. of 100	Full Box Only

Technical Parameters

Diameter	M8
Length	50 mm
Class	4.8
Driving features	Slotted
Head shape	Button head
Material	Steel
Surface treatment	Zinc plated
Thread	Metric thread

Standards

NF	E25-129
----	---------

Technical Specification

d-D	M8
Thread length (min.)	38
dk (max.)	20
Full thread if $L \leq$	60
k (max.)	4.4
L (mm)	50
n	2
P	1.25
t (min.)	2

Technical Drawing

