


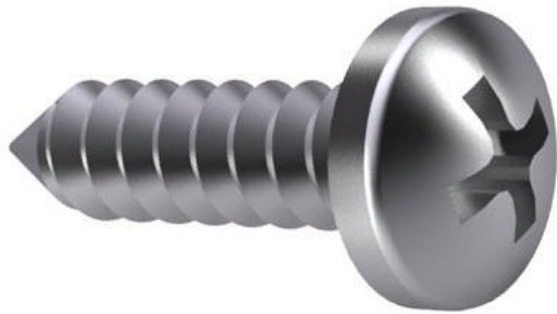

Cross recessed pan head tapping screw Phillips DIN 7981 C-H Steel Nickel plated ST3,9X19MM

Article number	26200.039.019
Brand	-
UBB	950352066068
UNSPSC	31161507
EAN	8715492652966
PKG. of 200	Full Box Only

Technical Parameters

Diameter	3.9 mm
Length	19 mm
Driving features	Phillips
Head shape	Pan head
Material	Steel
Surface treatment	Nickel plated
Thread	Self tapping thread

Info

Warning:
electroplating of
these products may
cause hydrogen
embrittlement.

Standards

DIN	7981 CH
NF	E25-658
ISO	7049 CH
ASME	B18.6.4

Technical Specification

D (mm)	3.9
dk	7.5
k	2.8
L (mm)	19
No. cross recess	2
P	1.4

Technical Drawing

