


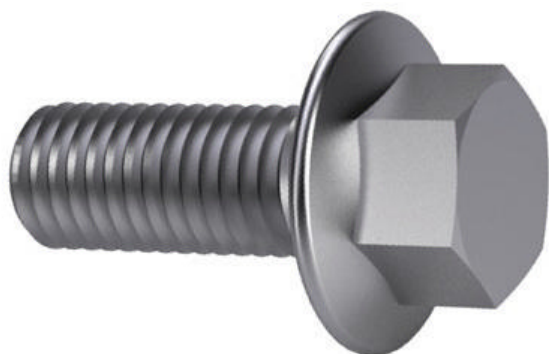

**Hex washer head thread
rolling screw Steel Zinc
plated #10-24X3/8**

Article number	26560.048.009
Brand	-
UBB	500656788774
UNSPSC	31161507
EAN	8712423027459
PKG. of 1000	Full Box Only

Technical Parameters

Diameter	NO.10
Length	3/8 Inch
Driving features	Hexagon
Head shape	Flange head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Unified National Coarse

Standards

ASME	B18.6.4 C
------	-----------

Technical Specification

A	0.312
B (max.)	0.414
H (max.)	0.151
TPI	24

Technical Drawing

