


MAXXFAST Cavity fixing Steel Zinc plated M4X21

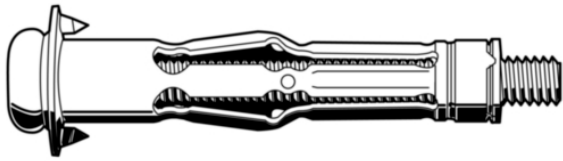

Article number	30537.040.021
Brand	-
UBB	500619769119
UNSPSC	31162103
EAN	8715494125437
PKG. of 50	Full Box Only

Technical Parameters

Diameter	M4
Length	21 mm
Material	Steel
Surface treatment	Zinc plated
Thread	Metric thread
Type no.	H-FAST
Info	Pull-out force for maximum plasterboard thickness.

Standards

Technical Specification

Cavity depth (min.)	26
d-D	M4
Drill ø	8
L (mm)	21
Screw length	28
Thickness of the fixture	1

Technical Drawing

